



Rectangle Ring Terminal

T&B Catalog Number:

A485

UPC Number:

78621080870

Status:

Active

Description:

Non-Insulated Rectangular Ring Terminal, Length .87 Inches, Width .237 Inches, Bolt Hole #4, Wire Range #22-#18 AWG, Copper, Tin Plated


WEB_USE

US Cutsheet PDF Catalog Link

<http://www-public.tnb.com/contractor/docs/stakon.pdf>

Features

Funneled Barrel Entry, Deep Internal Serrations, Brazed or overlapping seams.

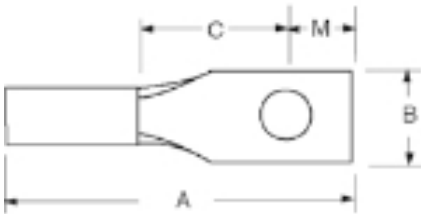

General

Insulation Type	Non-Insulated
Terminal Series	A
Material	Copper
Finish	Electro -Tin Plated
Color	Metallic
Wire Range	22-18
Stud Size	#4
Bu-Ships Tongue Shape	L85

Dimension Information

Stock Thickness	.03
A (inches)	.87
B (inches)	.24
C (inches)	.40
M (inches)	.20

Specifications

Temperature Rating	150°C
Voltage Rating	600V
Flammability Rating	UL 94 V-0
MIL Specification	MS-21004-5

Tooling

Tool Charts	Available on Website
Application Tools	ERG4002
Recommended Tool	ERG4002

Packaging

T&B Order Multiple	1000
T&B Inner Pack	1000
Package in Units	10000
Package Type	Standard
T&B Sold in UOM	Each
T&B Weight Per UOM	1.88 lbs. per 1000

Application Support

Overview	Available on Website
Wire Guide Tables	Available on Website

Notes

22-18 ga. = 1-2 Navy

A, B, C485 for use with BU-Ships terminal board types 25TB and 27TB.

Certifications

RoHS Compliance Yes

Certifications



File Nbr:
E9809

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email:techsupport@tnb.com