



Features:

- For crimping 140 series contacts
- Crimp settings for common wires between 24 and 30 AWG
- Replacement parts are available for purchase separately (Refer to the following pages for part numbers)
- Adjustment settings for conductor and insulation crimp area
- Designed to be easily adjusted
- Quiet
- High strength and easy to operate
- Feed type: Mechanical / Pneumatic

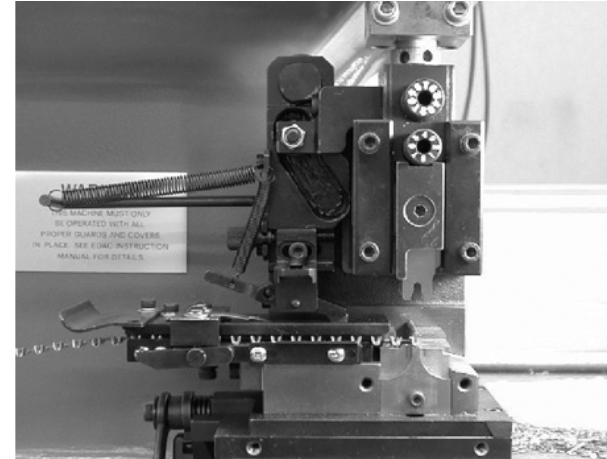


EDAC APPLICATOR - For use with EDAC Crimping Machine P/N 516-280-700

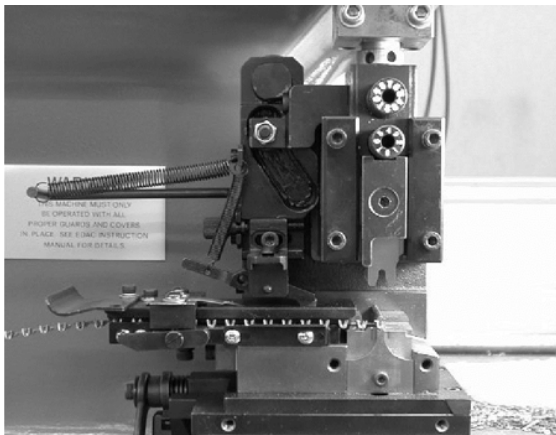

Press type	EDAC press
Stroke length	30.00mm
Shut height	119.55mm
AWG	24-30
Feed type	Mechanical / Pneumatic

G/K PRESS APPLICATORS – For use with G or K Crimping Machines

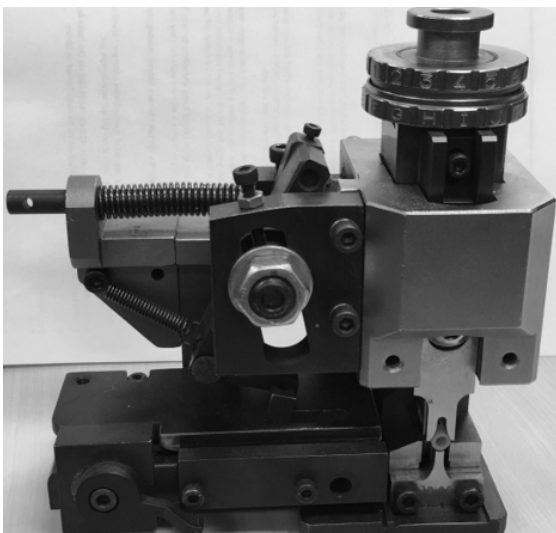


Press type	K / G press
Stroke length	30.00mm / 40.00mm
Shut height	119.55mm / 135.79mm
AWG	24-30
Feed type	Mechanical / Pneumatic


Contact number: 140-941-290 / 140-941-290P80

REPLACEMENT PARTS

Type of press	Applicator #	Insulator Anvil	Wire Anvil	Wire Crimper	Insulator Crimper	Cut-off Punch	Anvil Holder
EDAC press	140-280-751	140-281-004	140-281-005	140-281-032	140-281-033	140-281-031	140-281-038
K press	140-280-751K	140-281-004K	140-281-005K	140-281-032K	140-281-033K	140-281-031K	140-281-038K
G press	140-280-751G	140-281-004G	140-281-005G	140-281-032G	140-281-033G	140-281-031G	140-281-038G

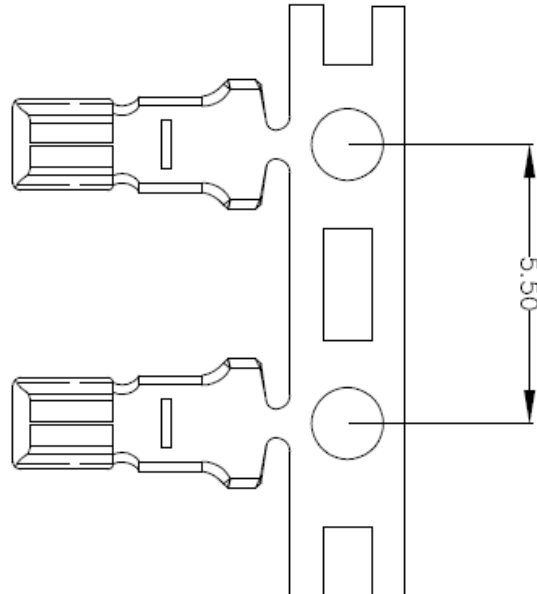

REPLACEMENT PARTS

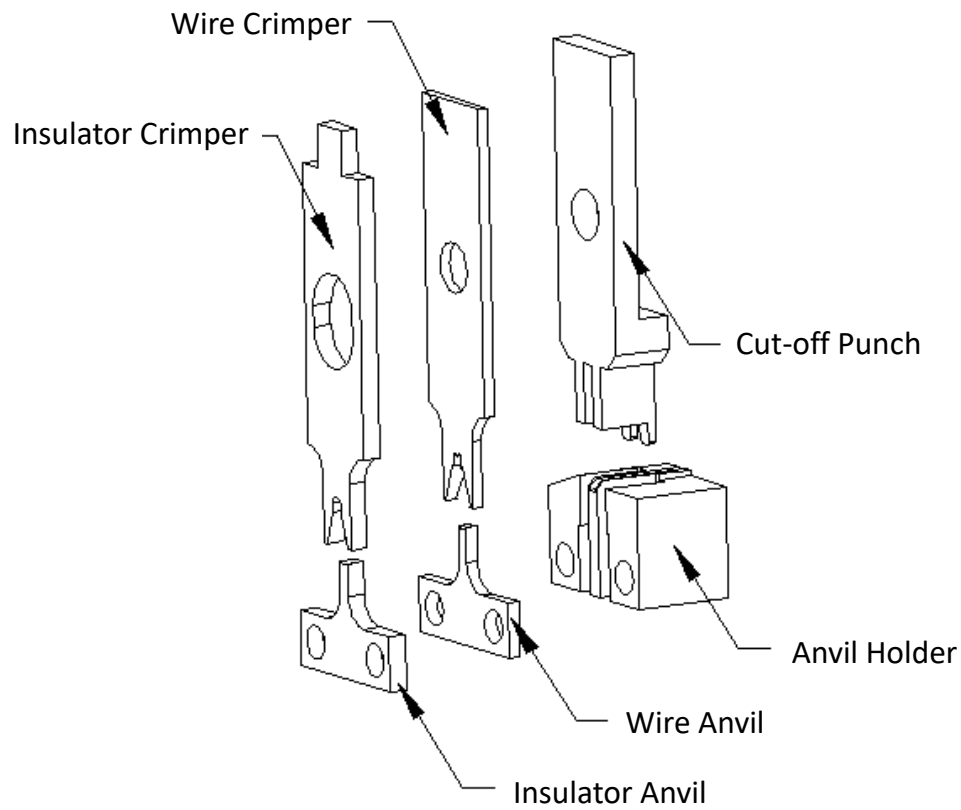

For additional questions please contact: customerservice@edac.net